


# COEUR-Enabled High-Voltage, High-Current Connectors

## PowerWize High-Voltage High-Current Connectors

Wire-to-Board  
Wire-to-Busbar

Current Rating:  
6.00mm: 120.0A  
8.00mm: 180.0A

Voltage Rating (max.): 1,000V  
6.00mm: 1,000V  
8.00mm: 1,500V

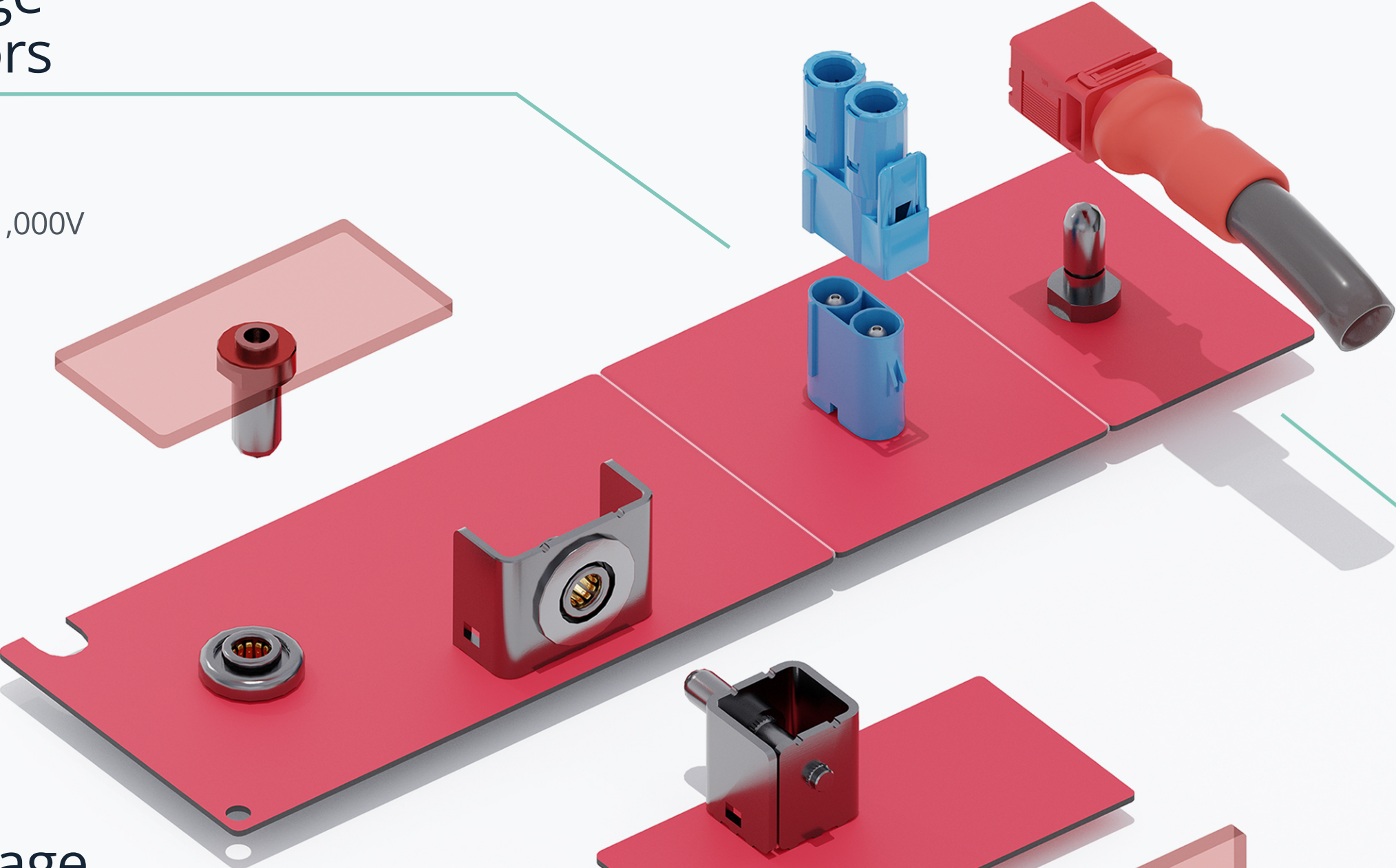

## SW1 High-Voltage High-Current Connectors

Wire-to-Board  
Wire-to-Busbar

Current Rating:  
6.00mm: 120.0A  
8.00mm: 185.0A  
11.00mm: 300.0A

Voltage Rating (max.): 1,500V

## Sentrality High-Voltage High-Current Connectors

Board-to-Board  
Board-to-Busbar  
Busbar-to-Busbar

Current Rating(max.):  
3.4mm: 75.0A  
6.00mm: 140.0A  
8.00mm: 200.0A  
11.00mm: 350.0A

Voltage Rating (max.): 1,500V